

LICENCE

No. 20642 replaces No.20306

Issued to:

Applicant:

La Triveneta Cavi S.p.A.

Via Orna, 35

36040 BRENDOLA (VI)

Italy

Licensee:

La Triveneta Cavi S.p.A.

Via Orna, 35

36040 BRENDOLA (VI)

Italy



Product : cables for fixed wiring

Trade name(s) : LTC

Type(s)/model(s) : XVB

The product and any acceptable variation thereto is specified in the annex to this licence and the documents therein referred to.


SGS CEBEC hereby declares that the above-mentioned product has been certified on the basis of:

- a type test according to the standard specified in annex
- an inspection of the production location
- a certification agreement with the number 579

SGS CEBEC hereby grants the right to use the CEBEC certification mark

The CEBEC certification mark may be applied to the product as specified in this licence for the duration of the CEBEC certification agreement and under the conditions of the CEBEC certification agreement.

This licence is issued on: 30/01/2018

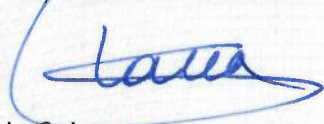

ir. C. Lana,
Certification Manager

© Only integral publication of this certificate, including the annex, is allowed

This certificate is only valid combined with the publication on the following web address: www.sgs.com/ee



SGS Belgium NV-Division SGS CEBEC
Business Riverside Park
Bld Internationalelaan 55 Build. D
B-1070 Brussels
Tel.+32(0)2 556 00 20 Fax.+32(0)2 556 00 36

This certificate is issued by the company under its General Conditions for Certification Services accessible at http://www.sgs.com/terms_and_conditions.htm. Attention is drawn to the limitations of liability defined therein and in the Test Report herein mentioned which findings are reflected in this Certificate. Any unauthorized alteration, forgery or falsification of the content or appearance of this document is unlawful and offenders may be prosecuted to the fullest extent of the law.

SPECIFICATION OF THE CERTIFIED PRODUCT

Product data

Product	:	cables for fixed wiring
Trade name(s)	:	LTC
Type(s)/Model(s)	:	XVB
description	:	cable with copper conductors, unarmoured, XLPE insulated and PVC sheathed
rated voltage U ₀ /U	:	0,6/1 kV
Fire propagation	:	Minimum: Cca-s3,d2

Additional information

Covered cross sections and number of conductors.

1-core : 16 mm² to 300 mm²

2-core: 1.5 mm² to 25 mm²

3 -core: 1.5 mm² to 50 mm²

4-core: 1.5 mm² to 50 mm²

5-core: 1.5 mm² to 35 mm²

3-core: 25 mm² to 50 mm² + 1-core: 16 mm² to 25 mm²

7, 9, 10, 12, 14, 19-core: 1.5 mm²

TESTS

Test requirements

NBN HD 604:2016

Remarks

This certificate is based on test reports Nr.612170.01a, 612170.01b, 612170.01c and 519C-626889/01

Conclusion

The examination proved that all test requirements were met.

Checked by, project leader : Luigi Zanutto - 30/01/2018

Department Manager,
Product Certification :

Certification Manager :

 2018-01-30

FACTORY LOCATION(S)

La Triveneta Cavi S.p.A.
Via Orna, 35
36040 BRENDOLA (VI)
Italy